

## Engineering Specification

Job Name \_\_\_\_\_

Contractor \_\_\_\_\_

Job Location \_\_\_\_\_

Approval \_\_\_\_\_

Engineer \_\_\_\_\_

Contractor's P.O. No. \_\_\_\_\_

Approval \_\_\_\_\_

Representative \_\_\_\_\_

# HY-600


## Non-Freeze Post Hydrant Specification

Watts HY-600 non-freeze key operated post hydrant with decorative epoxy coated cast iron housing, all bronze head, seat casting and internal working parts, galvanized casing, and loose key.

Call customer service if you need assistance with technical details.

Depth of Bury		
Suffix	Description	
-2	2'(610) Depth	<input type="checkbox"/>
-3	3'(914) Depth	<input type="checkbox"/>
-4	4'(1219) Depth	<input type="checkbox"/>
-5	5'(1524) Depth	<input type="checkbox"/>
-6	6'(1829) Depth	<input type="checkbox"/>
-8	8'(2438) Depth	<input type="checkbox"/>

Inlet/Outlet Sizing		
Suffix	Description	
-3/4	3/4"(19) Connection Size	<input type="checkbox"/>
-1"	1"(25) Connection Size	<input type="checkbox"/>
-1 1/2"	1 1/2"(38) Connection Size	<input type="checkbox"/>
-2	2"(51) Connection Size	<input type="checkbox"/>

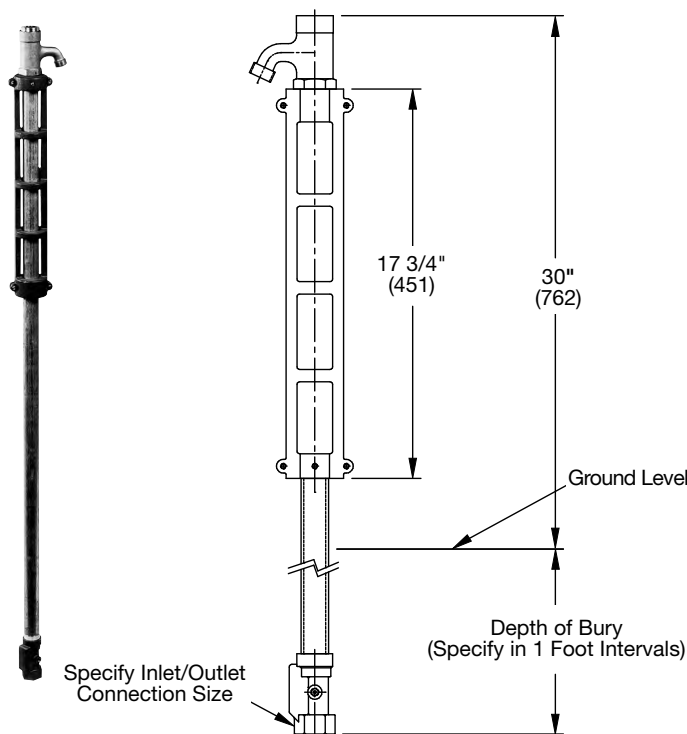

### NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Watts product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Watts Technical Service. Watts reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Watts products previously or subsequently sold.



USA: T: (800) 338-2581 • Watts.com

Canada: T: (888) 208-8927 • Watts.ca

Latin America: T: (52) 55-4122-0138 • Watts.com

ES-WD-HY-600 2404

© 2024 Watts

