

VisuGuard® T/P

Series F727

Series F727

T/P Total Protection: Temperature Display Featuring:

- Precise temperature readout within 1/10th of a degree
- Affordably priced, comparable to common pressure balance valves
- Provides true protection against pressure and temperature changes
- Eliminates time and cost for seasonal limit stop adjustments
- Controls mixed outlet temperature within 10°F of hot water supply temperature for applications where low hot water temperatures exist
- 5-Year Limited Warranty on internal tempering mechanism
- Won't stick or seize due to harsh water conditions
- Back-to-back installation without costly cross-over piping
- Self-contained cartridge installs in minutes to simplify repairs
- ASSE 1016 Type T/P and cUPC listed
- Tested to ASSE 1016 Type T/P and CSA B125.1 standards




Serving hotel, healthcare, education, commercial
and residential markets since 1891.



POWERS™

Complete shower systems featuring VisuGuard® T/P temperature displays...

- Deluxe or standard chrome-plated brass components
- Valve housing is 100% cast bronze
- Compensates for 50%+ fluctuation in supply line pressures*
- Compensates for 25°F increase in hot water supply temperature*
- Battery operation provides years of service
- Watertight housing protects electronics

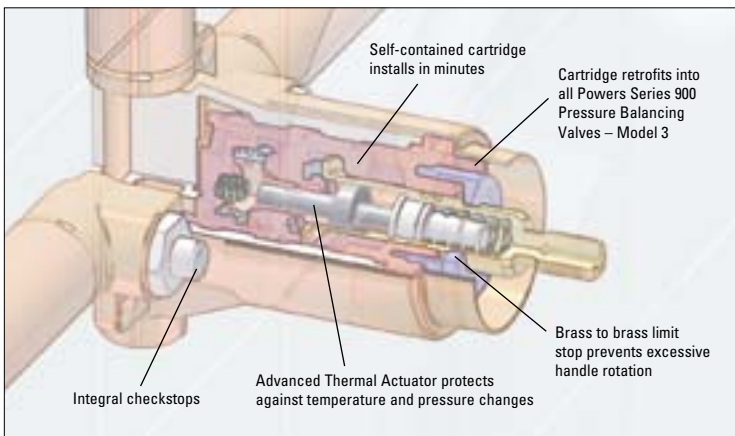

Advanced Thermal Actuation technology maintains a safe and constant output flow despite changes in input temperature or pressure – dramatically minimizing the risks of scalding and facility liability...



141 163 Shown



F727M1U000 Tub and Shower Assembly Shown

* See ASSE Standard 1016 Type T/P

System components combine beauty and functionality...



141 371 & 141 399 Shown



141 376 & 141 399 Shown



141 409 Shown

Tub spouts are available with and without diverters in 1/2" and 3/4" inlets. All spouts are chrome-plated.



141600B Shown



141 319 Shown

Deluxe chrome-plated brass faceplate and handle provide lasting performance and an attractive appearance.

Showerheads are available in four models: deluxe chrome-plated brass, standard chrome-plated brass, adjustable massage, and economizer chrome-plated ABS. Arm and flange options include standard and deluxe chrome plated brass.

Diverters are available concealed or exposed. Vacuum breakers are available as elevated with chrome plating or as in-line.

For specifications call 800-669-5430 or visit www.powerscontrols.com



POWERS™

A Watts Water Technologies Company

ISO 9001-2008 CERTIFIED

USA: Phone: 1.800.669.5430 • Fax 1.847.229.0526 • www.powerscontrols.com
 Canada: Phone: 1.888.208.8927 • Fax 1.888.479.2887 • www.powerscontrols.ca