

tekmar® Submittal

24 V (ac) Transformer 009



Accessories


009_C

05/14

Replaces: 11/12

Job _____ Designer _____ Contact _____

The Transformer 009 is a 40 VA, 24 V (ac) transformer for use with products that require an external transformer. There is an in-line fuse that comes with the transformer for circuit protection.

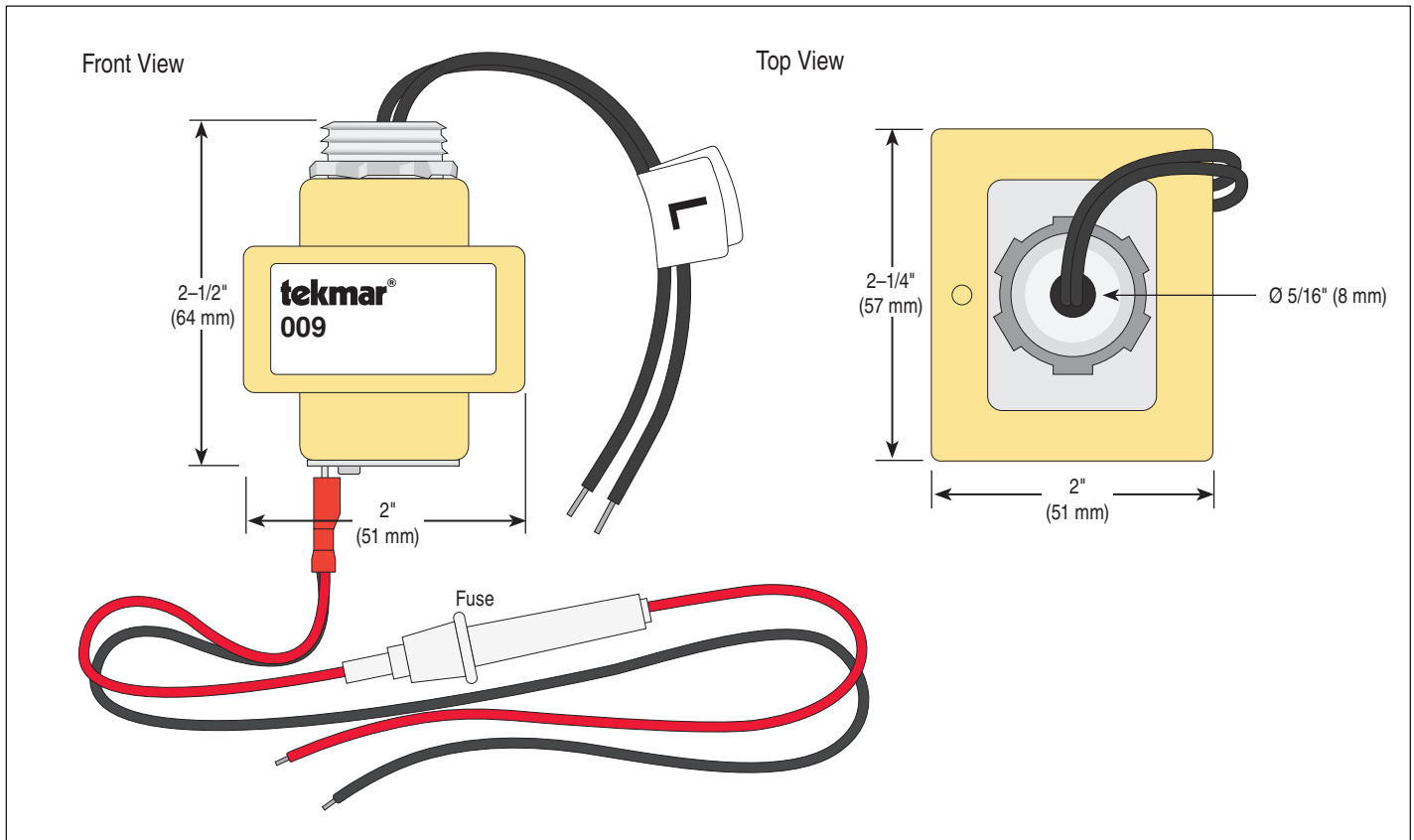

Specifications

24 V (ac) Transformer 009 40 VA	
Literature	009_D
Packaged weight	1.6 lb (750 g)
Dimensions	2" W x 2-1/4" L x 2-1/2" D (51 x 57 x 64 mm)
Approvals	CSA standard C22.2 #66 part B & UL 5085
Ambient conditions	Indoor use only, 32 to 104°F (0 to 40°C)
Input power supply	120 V (ac) ± 10%, 60 Hz
Output power available	24 V (ac) ± 10% 60 Hz, 1.67A, 40 VA, Class 2
Supplied fuse rating	T2 A 250 V slow-blow
Warranty	Limited 3 Year (See 009_D for full warranty)

Features

- 24 V (ac), 40 VA transformer
- Color coded wiring for easy in-phase wiring
- Replaceable in-line fuse included

SPECIAL REQUIREMENTS

N / A



tekmar Control Systems Ltd., A Watts Water Technologies Company. Head Office: 5100 Silver Star Road, Vernon, B.C. Canada V1B 3K4, 250-545-7749, Fax. 250-545-0650 Web Site: www.tekmarControls.com

