

For Commercial Applications

Job Name _____
 Job Location _____
 Engineer _____
 Approval _____

Contractor _____
 Approval _____
 Contractor's P.O. No. _____
 Representative _____
 SKU _____

Natural Gas Line Regulator

R325N32-0711-08 (2 PSIG Gas System)

1/2" NPT Female X 1/2" NPT Female

R625N42-0711-08 (2 PSIG Gas System)

3/4" NPT Female X 3/4" NPT Female


Line pressure regulators for 2 psi piping systems for use on residential, commercial and industrial applications. Features a high leverage linkage assembly to deliver positive dead-end lock-up. The regulators are capable of precise regulating control from full flow down to pilot flow. Housings are high strength aluminum castings and all models are suitable for multi-positional mounting. If ball check vent limiting device is installed, mount in an upright position only.




R325N32-0711-08 and R625N42-0711-08
(2 PSIG Gas System)

Technical Data

ITEM	CAPACITY	MAX IND. LOAD	MAX INLET PRESSURE	TEMPERATURE LIMITS	SPRING RANGE	SPRING SET POINT	DESIGN CERTIFICATIONS
	(BTU/HR)	(BTU/HR)	PSI (kPa)	Degrees Fahrenheit	" WC	" WC	CSA (C and US)
R325N32-0711-08	250,000	140,000	2 (13.8)	-40 to 205	7 - 11	8	ANSI Z21.80/CSA 6.22
R625N42-0711-08	600,000	425,000	2 (13.8)	-40 to 205	7 - 11	8	ANSI Z21.80/CSA 6.22

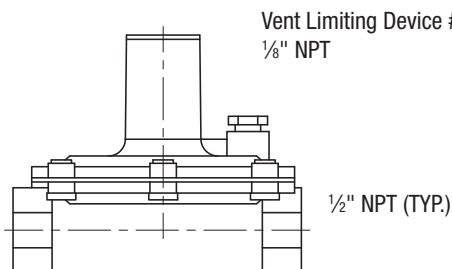

R325N32-0711-08 (2 PSIG Gas System)

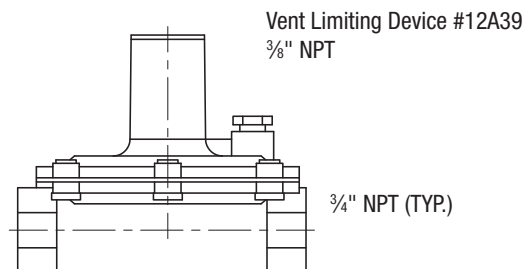

R625N42-0711-08 (2 PSIG Gas System)

NOTICE

Vent limiting devices are designed for use indoors and in spaces where limiting the amount of gas escapement due to diaphragm failure is critical. Vent limiting devices should not be used outdoors if they are exposed to the environment. Vent protectors are available for all outdoor applications to ensure proper vent protection. 13A15 (1/8" NPT) and 13A15-5 (3/8" NPT).

Maxitrol Regulator distributed by Dormont. Models 325-3L and 325-5L Series Lever Acting Design.

Dormont product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Dormont Technical Service. Dormont reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Dormont products previously or subsequently sold. Refer to the owner's manual for warranty information.



A Watts Water Technologies Company

USA: Tel: (800) 367-6668 • Fax: (724) 733-4808 • Dormont.com

Canada: Tel: (905) 332-4090 • Fax: (905) 332-7068 • Dormont.ca

Latin America: Tel: (52) 81-1001-8600 • Fax: (52) 81-8000-7091 • Dormont.com