

For Commercial Applications

Job Name _____
 Job Location _____
 Engineer _____
 Approval _____

Contractor _____
 Approval _____
 Contractor's P.O. No. _____
 Representative _____
 SKU _____

Convertible Gas Regulator for Natural Gas and LP

RV48CL-32 (1/2 PSIG Gas System)

1/2" NPT Female X 1/2" NPT Female

RV48CL-42 (1/2 PSIG Gas System)

3/4" NPT Female X 3/4" NPT Female


Gas appliance regulators are designed for main burner and/or pilot applications, where precise control of tiny flows is an essential operating requirement. Housings are high strength aluminum castings and all models have been tested for multi-position and may be installed in any plane or angle without restriction. They may be used with natural, manufactured, mixed LP, or LP gas-air mixture.




RV48CL-32_42 (1/2 PSIG Gas System)

Technical Data

ITEM	CAPACITY (BTU/HR)	MAX INLET PRESSURE PSI (mbar)	TEMPERATURE LIMITS Degrees Fahrenheit	SPRING SET POINT " wc NG	SPRING SET POINT CONVERTIBLE TO " wc LP	DESIGN CERTIFICATIONS CSA (C and US)
RV48CL-32	230,000	1/2 (34)	32 - 275	5	10	ANSI Z21.18/CSA 6.3
RV48CL-42	275,000	1/2 (34)	32 - 275	5	10	ANSI Z21.18/CSA 6.3

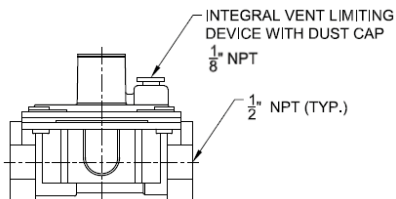

RV48CL-32 (1/2 PSIG Gas System)

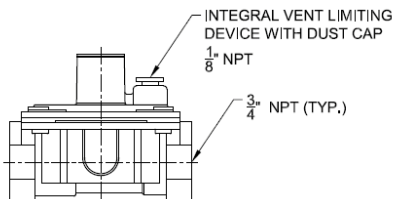

RV48CL-42 (1/2 PSIG Gas System)

Maxitrol Regulator distributed by Dormont. Model RV48CL Series Rubber Seat Poppet Design.

Dormont product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Dormont Technical Service. Dormont reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Dormont products previously or subsequently sold. Refer to the owner's manual for warranty information.



A WATTS Brand

USA: T: (800) 367-6668 • F: (724) 733-4808 • Dormont.com
 Canada: T: (905) 332-4090 • F: (905) 332-7068 • Dormont.ca
 Latin America: T: (52) 81-1001-8600 • Dormont.com