

Engineering Specification

Job Name _____
 Orion Representative _____
 Quantity Required _____


Contractor Signature _____
 Approval Date _____
 Contractor's P.O. No. _____

T10 Point-Of-Use Dilution Tank

Specification

Orion T10 POU 1.5 USG Tank shall be cylindrical seamless, stress and defect free, rotationally molded construction with integral cover to uniform wall thickness from virgin PE resins conforming to ASTM D 1248, with **FIP adjustable inlet(s) with dip tube(s), with single MIP outlet and 2" top cleanout as standard.** All penetrations shall be heat fused to tank wall.

Tank Selection (Check One)		
Part No.	Description	
<input type="checkbox"/>	736000	Two 1.5" FIP Inlets, One 2" MIP Side Outlet, Black
<input type="checkbox"/>	736004	Two 1.5" FIP Inlets, One 2" MIP Side Outlet, White
<input type="checkbox"/>	736001	One 1.5" FIP Inlets, One 2" MIP Side Outlet, Black
<input type="checkbox"/>	736005	One 1.5" FIP Inlets, One 2" MIP Side Outlet, White
<input type="checkbox"/>	736003	Two 2" FIP Inlets, One 2" MIP Side Outlet, Black
<input type="checkbox"/>	736007	Two 2" FIP Inlets, One 2" MIP Side Outlet, White
<input type="checkbox"/>	736002	One 2" FIP Inlets, One 2" MIP Side Outlet, Black
<input type="checkbox"/>	736006	One 2" FIP Inlets, One 2" MIP Side Outlet, White

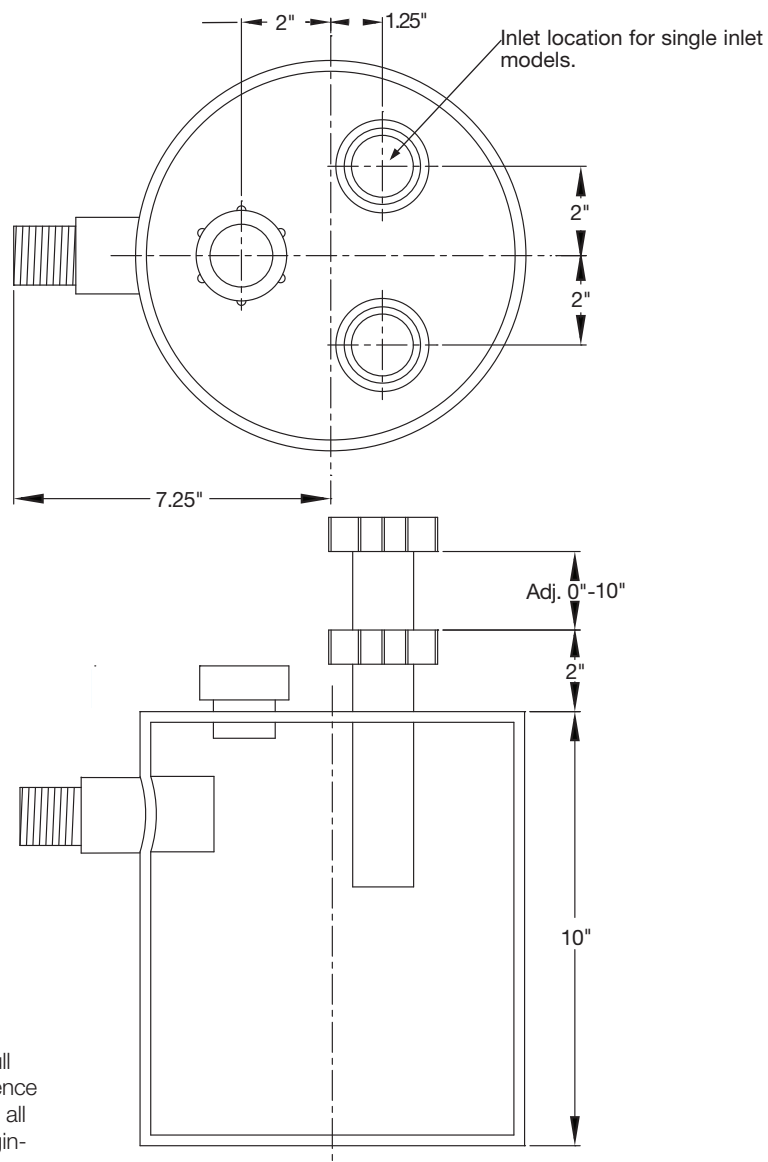

Note: Tanks are made to ±0.25 in. tolerance.

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Please verify all selections with your local Orion rep - tank products and accessory equipment are non-returnable.

Orion Fittings product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Orion Fittings Technical Service. Orion Fittings reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Orion Fittings products previously or subsequently sold.



USA: T: (800) 334-6259 • OrionFittings.com
Canada: T: (888) 208-8927 • F: (888) 479-2887 • OrionFittings.ca
Latin America: T: (52) 55-4122-0138 • OrionFittings.com

A WATTS Brand