

Engineering Specification

Job Name _____
 Job Location _____
 Engineer _____
 Approval _____

Contractor _____
 Approval _____
 Contractor's P.O. No. _____
 Representative _____

Hand Showers

Part No. 141 161N

Specifications

Description Hand Shower with 3-Position Wall Mount, 2/Kit Type 5

Finish See table and drawing

Agency/Spec Approval IAPMO cUPC
 ASME A112.18.1
 CSA B125.1


Maximum Flow 2.5 gpm (9.5L/min) MAX at 80 psi

Minimum Flow 1.8 gpm (6.8L/min) MIN at 45psi

Shipping Weight 2.03 lb. (0.92 kg)



Detail

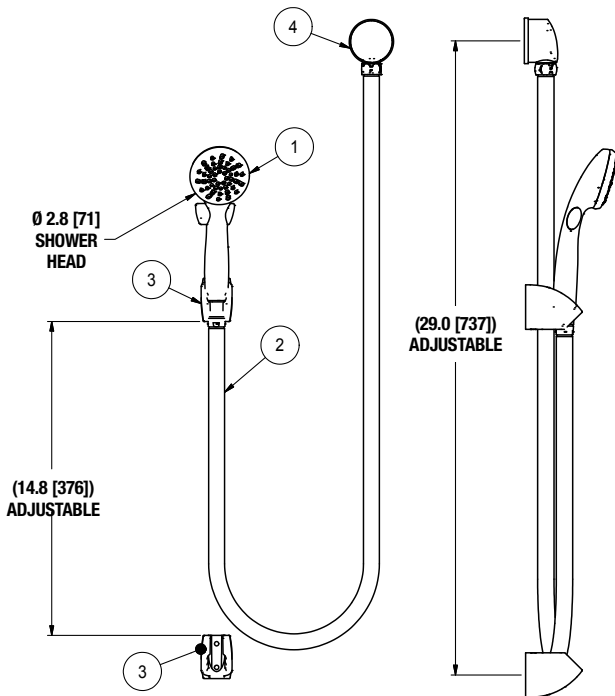

Call customer support if you need assistance with technical details.

Part No. 141 161N

ITEM	MODEL	DESCRIPTION	QTY
1	141161AN	Hand Sprayer, Push Button, CP Plastic, 2.50 GPM	1
2	141161BN	Hose, Stainless Steel, 60 Inches	1
3	141161DN	Wall Mount, 3-Position W/Screws & Plugs	2
4	141320N	Supply Elbow CP Plastic Cover, Brass 1/2" NPT	1

Powers product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Powers Technical Service. Powers reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Powers products previously or subsequently sold.



USA: Tel: (888) 432-8932 • PowersControls.com
Canada: Tel: (888) 208-8927 • PowersControls.ca
Latin America: Tel: (52) 55-4122-0138 • PowersControls.com

